

連接電纜

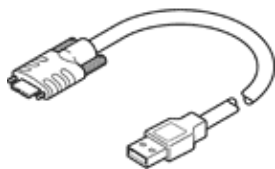

NEBC-U7G10-KS-5-N-S-U5G9

料號: 8072582
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

10 9 8 7 6 5 4 3 2 1



技術參數

特性	值
Cable identification	Without inscription label holder
產品重量	422 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	USB 3.0 type A
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	9
工作電壓範圍 DC	0 ... 30 V
在40°C時的可接受電流負載	1.8 A
浪湧強度	0.3 kV
電纜長度	5 m
電纜屬性	標準
電纜的測試條件	視需求的測試條件
Bending radius, fixed cable installation	>= 125 mm
Bending radius, flexible cable installation	>= 125 mm
電纜直徑	6.2 mm
電纜結構	2 x AWG22 + 2 x (2 x AWG26)C + 1 x (2 x AWG28) 已屏蔽
導體的額定截面	0.08 mm ² 0.128 mm ² 0.324 mm ²
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-20 ... 80 °C
Ambient temperature with flexible cable installation	-20 ... 80 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS 不含鹵素
污染程度	1
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	PVC
電纜外套顏色	黑色