

## 連接電纜

### NEBC-U7G10-EH-15-N-S-U5G9


料號: 8093271

將停止供貨的產品

FESTO

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

10 9 8 7 6 5 4 3 2 1

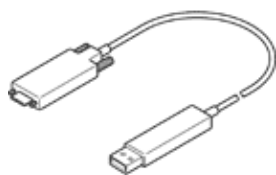

## 技術參數

特性	值
附加功能	Hybrid cable
Cable identification	Without inscription label holder
產品重量	444 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	USB 3.0 type A
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	9
Electrical connection 2, type of mounting	Plug-in
工作電壓範圍 DC	4.75 ... 5.25 V
額定工作電壓 DC	5 V
在40°C時的可接受電流負載	0.9 A
電纜長度	15 m
電纜屬性	適合於拖鏈
Bending radius, fixed cable installation	>= 20 mm
Bending radius, flexible cable installation	>= 10 mm
電纜直徑	3.1 mm
電纜直徑公差	± 0,2 mm
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
Ambient temperature with flexible cable installation	-5 ... 50 °C
儲藏溫度	-40 ... 90 °C
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
污染程度	1
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	PVC
電纜外套顏色	黑色
Material housing	Anodised wrought aluminium alloy
外殼顏色	銀