 



轉接器

NEFM-S1G9-K-0,5-R3G8

料號: 8106112

FESTO

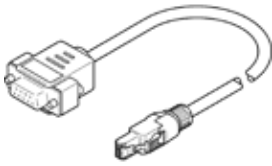

技術參數

特性	值
Cable identification	Without inscription label holder
產品重量	100 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	8
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	RJ45
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	8
工作電壓範圍 DC	0 ... 24 V
額定工作電壓 DC	24 V
在40°C時的可接受電流負載	0.9 A
浪湧強度	2 kV
Shielding	是
電纜長度	0.5 m
電纜屬性	標準
Bending radius, fixed cable installation	68 mm
電纜直徑	6.8 mm
電纜結構	5x(2x0,08)
導體的額定截面	0.08 mm ²
Nominal conductor cross section (AWG)	AWG28
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-20 ... 80 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	2
Material cable sheath	PVC
電纜外套顏色	黑色
Material housing	PVC
外殼顏色	黑色
Material insulation	PVC