


# 插座

## NEFV-V13-XX4G3-T1G3

料號: 8109877

FESTO

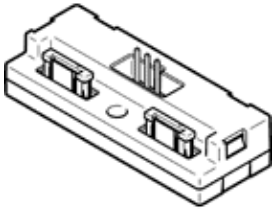

### 技術參數

特性	值
尺寸 寬(W) x 長(L) x 高(H)	18,7 mm x 50 mm x 15,3 mm
安裝類型	With through-hole for M3 screw
Cable outlet	直的
產品重量	6.8 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, connection technology	ZIF
Electrical connection 1, number of pins/wires	5
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Field device side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭插座
Electrical connection 2, connection technology	ZIF
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	3
Electrical connection 2, type of mounting	Plug-in
Electrical connection 3, function	Controller side
Electrical connection 3, design	有角的
Electrical connection 3, connection type	插頭
Electrical connection 3, connection technology	Festo-specific coding
Electrical connection 3, number of pins/wires	3
Electrical connection 3, occupied pins/wires	3
Electrical connection 3, type of mounting	Plug-in
工作電壓範圍 DC	0 ... 310 V
保護性接地	還未上市
Shielding	否
防護等級	IP40
Note on degree of protection	裝配狀態
環境溫度	-10 ... 60 °C
儲藏溫度	-40 ... 80 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	2
耐腐蝕等級 CRC	1 - Low corrosion stress
Material housing	PA
外殼顏色	黑色
Material electrical contact	Nickel-plated and gold-plated bronze