 



# 垂直壓力氣源板

## VMPA14-VSP-QS3/8

料號: 8110623

FESTO

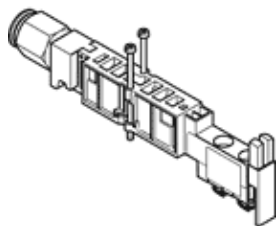

### 技術參數

| 特性                     | 值                             |
|------------------------|-------------------------------|
| 網柵尺寸                   | 14 mm                         |
| Operating pressure MPa | -0.09 ... 1 MPa               |
| 操作壓力                   | -0.9 ... 10 bar               |
| Pilot pressure MPa     | 0.3 ... 0.8 MPa               |
| 嚮導壓力                   | 3 ... 8 bar                   |
| 操作介質                   | 壓縮空氣符合 ISO8573-1:2010 [7:4:4] |
| 耐腐蝕等級 CRC              | 1 - Low corrosion stress      |
| PWIS conformity        | VDMA24364-B1/B2-L             |
| 環境溫度                   | -5 ... 50 °C                  |
| 產品重量                   | 55 g                          |
| 氣壓連接, 氣口 1             | QS-3/8                        |
| 材料備註                   | 符合 RoHS                       |
| Material supply plate  | PA-加強                         |