


# 氣壓接口 VABA-S6-1-X2-3V-CB-AL

料號: 8152438

FESTO

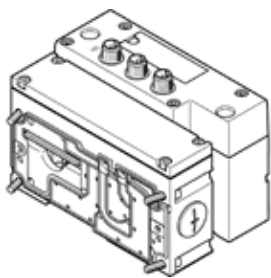

## 技術參數

特性	值
閥島介面	44型, VTSA
診斷	Wire break per valve coil Short circuit of valves 低電壓閥
閥位的最大數量	12 with bistable valves 24 適用於單穩態閥
LED顯示	1 group diagnostics 3 load supply Channel status on valves
參數配置	Fail-safe mode per channel Forcing per channel Idle mode per channel Module monitoring
防護( 短路 )	每個閥輸出的內部電子保險絲保護
工作電壓範圍 DC	21.6 ... 26.4 V
操作電壓時的內部電流耗損量	Typically 11 mA (operating voltage supply for electronics) Typically 45 mA (load voltage supply for valves)
每一通道最大的電源供應	0,2 A
每一模組最大的集合氣流量	6 A
額定工作電壓 DC	24 V
電絕緣通道 - 內部匯流排	是
耐腐蝕等級 CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
防護等級	IP65 NEMA 4
環境溫度	-5 ... 50 °C
產品重量	1,388 g
電氣連接	Fieldbus 3x M12x1, A-coded 5-pin 插頭 通過CPX
材料備註	符合 RoHS
Material cover	PA
Material housing	壓鑄鋁