


制動阻力 CACR-LE2-6-W60-V

料號: 8189339
新

FESTO

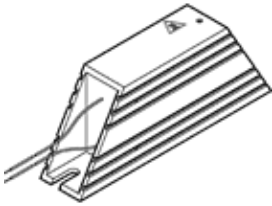

技術參數

特性	值
裝配置置	自由對流 垂直
Pulse energy, braking resistor at 380 V	2,000 Ws
Pulse energy, braking resistor at 780 V	2,000 Ws
35% 的功率周期以及 20°C 時的性能	180 W
額定功率, 制動阻力	60 W
Rated output, braking resistor at 380 V	60 W
Rated output, braking resistor at 780 V	60 W
阻力係數	6 Ohm
授權	c UL us - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Max. surface temperature	250 °C
Note on surface temperature	Indication at nominal power, at 50% nominal power: 165 °C
防護等級	IP54
環境溫度	-40 ... 40 °C
產品重量	150 g
安裝類型	具通孔
材料備註	符合 RoHS