
 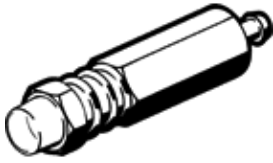


# pressure indication OH-8-GE

Part number: 10091

FESTO



## Data sheet

Feature	Value
Operating pressure MPa	-0.1 ... 0.8 MPa
Operating pressure	-1 ... 8 bar -14.5 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Pneumatic connection	Barbed fitting PK-3
Materials note	Conforms to RoHS