 



pneumatic valve J-3-PK-3

Part number: 10772

FESTO

This type is suitable for vacuum.

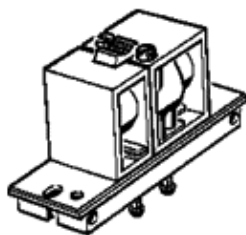

Data sheet

Feature	Value
Valve function	3/2 bistable
Standard nominal flow rate	100 l/min
Operating pressure	-0.9 ... 8 bar
Design structure	Piston slide
Nominal size	2.5 mm
Switching time reversal	7 ms
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
PWIS conformity	VDMA24364 zone III
Ambient temperature	-10 ... 60 °C
Product weight	75 g
Mounting type	On sub-base On mounting frame with through hole Optional
Auxiliary pilot air port 12	PK-3
Auxiliary pilot air port 14	PK-3
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Material of connecting plate	Brass PPS-reinforced
Material seals	NBR
Material housing	Plastic Zinc die-casting