
 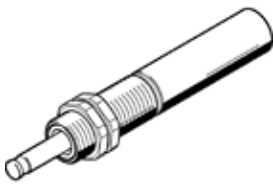


# shock absorber DYSR-32-60-Y5

Part number: 1138649

FESTO



## Data sheet

Feature	Value
Size	32
Stroke	60 mm
Cushioning	adjustable
Assembly position	Any
Position detection	No
Max. impact speed	3 m/s
Reset time short	0.6 s
Reset time long	3 s
Mode of operation	single-acting pushing action
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 80 °C
Cushioning length	60 mm
Max. stop force	6,400 N
Max. energy consumption per stroke	384 J
Max. energy consumption per hour	330,000 J
Max. residual energy	2 J
Reset force	18 N
Product weight	1,355 g
Mounting type	with lock nut
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	steel, galvanized
Material piston rod	High alloy steel, hardened