


Limit switch attachments

SRBF-CA5-YR90-MW-22A-C2M20

Part number: 1152497

FESTO

With mounting adapter, 30x130 mm hole pattern, for drives with 30 mm shaft height.

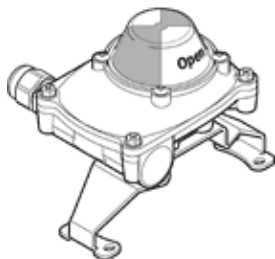

Data sheet

| Feature | Value |
|---|---|
| Design | Angular |
| Based on the standard | EN 60947-5-1 ISO 5211 |
| CE mark (see declaration of conformity) | to EU directive low-voltage devices |
| Materials note | Contains PWIS substances Conforms to RoHS |
| Measuring principle | Mechanical/electrical For proximity sensor |
| Ambient temperature | -25 ... 80 °C |
| Switching element function | Changeover switch |
| Max. contact rating AC | 1,770 VA |
| Max. contact rating DC | 36 W |
| Operating voltage range AC | 0 ... 250 V |
| Operating voltage range DC | 0 ... 24 V |
| Connectable nominal conductor cross section | 0.5 ... 1.5 mm ² |
| Mounting type | On flange to ISO 5211 with accessories |
| Assembly position | Any |
| Product weight | 710 g |
| Materials information, housing | Aluminium die cast Painted |
| Material information, accessories supplied | High alloy steel High alloy steel, non-corrosive |
| Setting range, angle recording | 0 ... 90 deg |
| Protection class | IP67 |
| Insulation voltage | 250 V |
| Surge strength | 4 kV |
| Corrosion resistance classification CRC | 0 |
| Degree of contamination | 3 |