

 

# solenoid valve

## MFH-5-PK-3-L

Part number: 11546

FESTO

With manual override, without solenoid coil or socket. Solenoid coil and socket should be ordered separately.

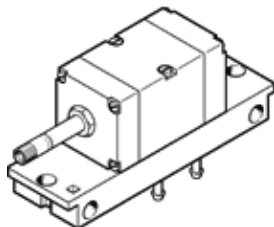

## Data sheet

Feature	Value
Valve function	5/2 monostable
Standard nominal flow rate	105 l/min
Operating pressure	1.5 ... 8 bar
Design structure	Poppet seat
Nominal size	2.5 mm
Sealing principle	soft
Switching time off	22 ms
Switching time on	14 ms
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-5 ... 40 °C
Product weight	270 g
Mounting type	On sub-base On mounting frame with through hole Optional
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium Anodised
Material seals	NBR
Material housing	Aluminium Anodised