


shock absorber DYEF-M12-Y1

Part number: 1179840

FESTO

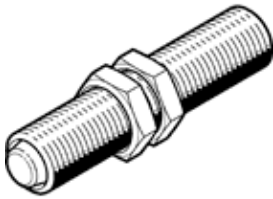

Data sheet

| Feature | Value |
|---|---------------------------------------|
| Size | M12 |
| Stroke | 1.2 mm |
| Cushioning | P cushioning without metal fixed stop |
| Assembly position | Any |
| Position detection | No |
| Max. impact speed | 0.8 m/s |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | 0 ... 60 °C |
| Cushioning length | 1.2 mm |
| Max. energy consumption per stroke | 0.35 J |
| Product weight | 45.5 g |
| Mounting type | with lock nut |
| Materials note | Conforms to RoHS |
| Material seals | NBR |
| Material housing | High alloy steel |