


barbed T-fitting TCN-1/8-PK-4

Part number: 11962

FESTO

For plastic tubing PAN, PUN, PP, PU, PR, with sealing ring, rotatable.

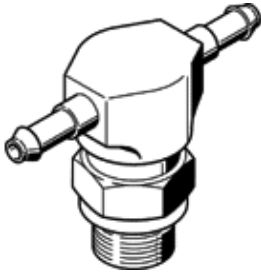

Data sheet

Feature	Value
Nominal size	2.9 mm
Type of seal on screw-in stud	Sealing ring
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 60 °C
Pneumatic connection, port 1	Male thread G1/8
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Conforms to RoHS
Material housing	Aluminium Zinc die-casting