


# flow control plate GRO-ZP-3-ISO

Part number: 119674

FESTO

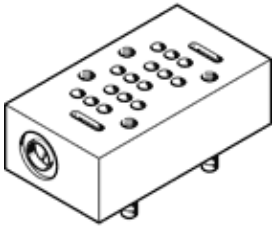

## Data sheet

Feature	Value
Valve function	Throttle function
Operating pressure	0 ... 16 bar
Standard nominal flow rate	1,500 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B2-L
Medium temperature	-20 ... 80 °C
Ambient temperature	-20 ... 80 °C
Mounting type	with through hole