


# solenoid coil MSN1G-24DC-OD

Part number: 123060

FESTO

For DC voltage, without plug socket.

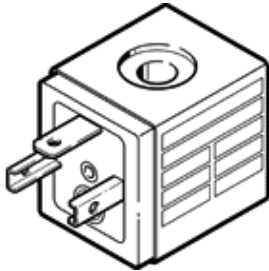

## Data sheet

Feature	Value
Assembly position	Any
Min. pickup time	10 ms
Duty cycle	100 %
Characteristic coil data	24 V DC: 2.5 W
Permissible voltage fluctuation	-15 % / +10 %
Authorisation	c UL us - Recognized (OL)
PWIS conformity	VDMA24364-C1-L
Medium temperature	-10 ... 50 °C
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Product weight	80 g
Electrical connection	3-pin Plug pattern type A to EN 175301-803 Per DIN EN 175301-803
Mounting type	Clamped with retaining clamp with accessories
Material housing	PA
Material electrical contact	Steel
Material winding	Copper