


solenoid coil

MSN1W-110AC-OD

Part number: 123061

FESTO

For AC voltage, without plug socket.

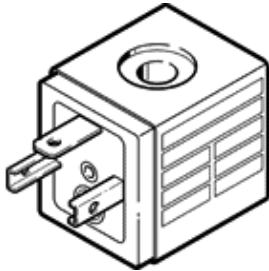

Data sheet

Feature	Value
Assembly position	Any
Min. pickup time	10 ms
Duty cycle	100 %
Power factor cos {phi}	0.7
Characteristic coil data	110 V AC: 50 Hz, pick-up power 7.5 VA, holding power 5 VA 110 V AC: 60 Hz, pick-up power 5 VA, holding power 3.7 VA 120 V AC: 60 Hz, pick-up power 5 VA, holding power 3.7 VA
Permissible voltage fluctuation	bei 50Hz ±10 % bei 60Hz -10...+20 %
Maritime classification	see certificate
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-C1-L
Medium temperature	-10 ... 50 °C
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Product weight	80 g
Electrical connection	3-pin Plug pattern type A to EN 175301-803 Per DIN EN 175301-803
Mounting type	Clamped with retaining clamp with accessories
Material housing	PA
Material electrical contact	Steel
Material winding	Copper