


## sub-base VABS-C8-12XB-QX-B

Part number: 1236025

Classic - do not use for new projects

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

**FESTO**

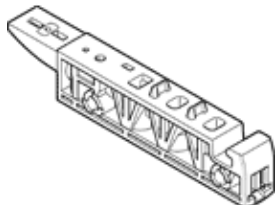

### Data sheet

Feature	Value
Width	12 mm
Max. number of valve positions	1
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.48 ... 0.72 Nm
Max. tightening torque, wall mounting	1.3 Nm
Product weight	15 g
Auxiliary pilot air port 12/14	prepared for cartridge
Pneumatic connection, port 1	Prepared for cartridge
Pneumatic connection, port 3	Prepared for cartridge
Pneumatic connection, port 5	Prepared for cartridge
Materials note	Conforms to RoHS
Material manifold	Reinforced PA