


# Short AVL-80-25-A

Part number: 12498

FESTO

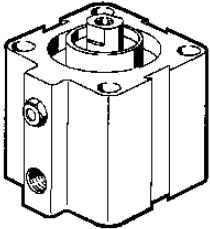

## Datasheet

Feature	Value
Mode of operation	Single, pushing
Shape piston	Round
Shape of piston rod	Round
Sensing type	Magnetic
Type of cushioning	None
Protection against torsion	None
Piston, nominal size	80
Stroke	25 mm
Piston rod diameter	20 mm
End of piston rod	Female thread
KK Piston rod thread	M 10
Operating pressure min.	0,5 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-20 °C
Maximum ambient temperature	60 °C
Material of barrel/housing	Aluminium
Air connection type cover cap	Female thread
EE Connecting thread for end cap	G 1/4
Effective force (theor.) at 6 bar, adv	.2870 N
Spring return force min.	84,5 N
Spring return force max.	112,5 N
Air consumpt.at 6 bar per advance stro	ke0,88 l
Medium	Compressed air, filtered