 



silencer U-3/8-B-NPT

Part number: 12740

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

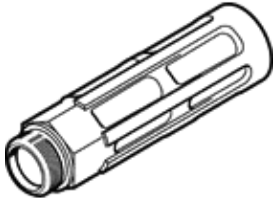

Data sheet

| Feature | Value |
|---|---|
| Assembly position | Any |
| Operating pressure for entire temperature range | 0 ... 1 MPa |
| Operating pressure complete temperature range | 0 ... 10 bar |
| Operating pressure for entire temperature range | 0 ... 145 psi |
| Flow rate to atmosphere | 4,500 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:::] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Sound pressure level | 80 dB(A) |
| Ambient temperature | -10 ... 70 °C |
| Product weight | 37 g |
| Pneumatic connection | 3/8 NPT |
| Material of silencer insert | PE |
| Material of threaded plug | Aluminium |
| Materials note | Conforms to RoHS |
| Material housing | Aluminium |