


# adapter plate

## VABA-S6-7-S2-3-P-N1

Part number: 1302085  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

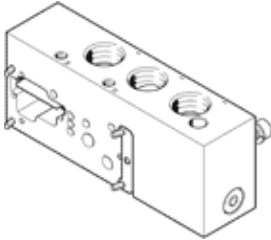

### Data sheet

Feature	Value
Width	60 mm
Assembly position	Any
Max. number of solenoid coils	26
Operating pressure	-0.9 ... 10 bar
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	2,600 g
Auxiliary pilot air port 12	1/8 NPT
Auxiliary pilot air port 14	1/8 NPT
Pneumatic connection, port 1	1 1/2 NPT
Pneumatic connection, port 3	1 1/2 NPT
Pneumatic connection, port 5	1 1/2 NPT
Materials note	Conforms to RoHS
Material seals	NBR
Material plate	Wrought Aluminium alloy
Material screws	Steel Galvanised