

# push-in T-fitting QSTL-B-3/8-6-10


Part number: 130984

Product to be discontinued

FESTO

360° orientable, male thread with external hexagon.

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

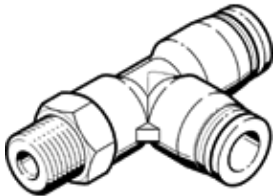

## Data sheet

Feature	Value
Size	Standard
Nominal size	3.2 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1
Ambient temperature	-10 ... 60 °C
Authorisation	Germanischer Lloyd
Max. tightening torque	22 Nm
Product weight	25.4 g
Number of outputs	2
Number of supply lines	1
Pneumatic connection, port 1	Male thread R3/8
Pneumatic connection, port 2	for tubing, 6mm outside diameter
Colour of release ring	blue
Materials note	Conforms to RoHS
Materials information, housing	PBT
Release ring material data	POM
Materials information for tubing seal	NBR
Hose clamping segment material data	High alloy steel, non-corrosive