


# cartridge QSPLLKG20-5/16-U

Part number: 132866

FESTO

With push-in connector, long L-form

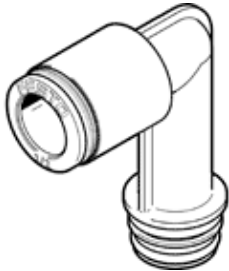

## Data sheet

Feature	Value
Size	Standard
Nominal size	4.8 mm
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-5 ... 60 °C
Product weight	11 g
Pneumatic connection, port 1	QSP...20
Pneumatic connection, port 2	for tubing, 5/16" outside diameter
Colour of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive