


push-in L-fitting
NPQP-LQ-R18-Q4-FD-P10
Part number: 133061

FESTO

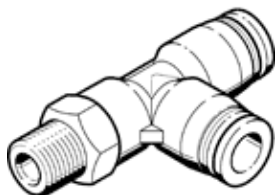

Data sheet

Feature	Value
Size	Standard
Nominal size	2 mm
Design	L-shape, additional push-in connector, lengthwise
Container size	10
Design structure	Push/pull principle
Temperature dependent operating pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	6 g
Mounting type	External hex A/F 10
Pneumatic connection, port 1	Male thread R1/8
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive