


# push-in L-fitting NPQP-LQ-R38-Q10-FD-P10

Part number: 133068

FESTO

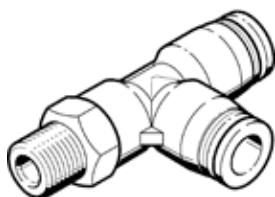

## Data sheet

| Feature                                  | Value  |
|--|--|
| Size                                     | Standard   |
| Nominal size                             | 5.8 mm   |
| Design                                   | L-shape, additional push-in connector, lengthwise        |
| Container size                           | 10   |
| Design structure                         | Push/pull principle                                      |
| Temperature dependent operating pressure | -0.95 ... 10 bar   |
| Operating medium                         | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium       | Lubricated operation possible                            |
| Corrosion resistance classification CRC  | 4 - Very high corrosion stress                           |
| PWIS conformity                          | VDMA24364 zone III                                       |
| Food-safe                                | See Supplementary material information                   |
| Ambient temperature                      | -20 ... 60 °C  |
| Product weight                           | 19 g   |
| Mounting type                            | External hex A/F 17                                      |
| Pneumatic connection, port 1             | Male thread R3/8   |
| Pneumatic connection, port 2             | For tubing outside diameter 10 mm                        |
| Materials note                           | Conforms to RoHS   |
| Material housing                         | PP   |
| Material of tube retaining claw          | High alloy steel, non-corrosive                          |