


push-in connector
NPQP-D-Q8-Q6-FD-P10
Part number: 133097

FESTO

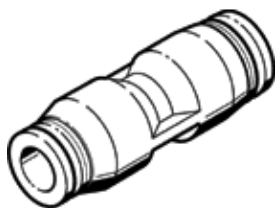

Data sheet

| Feature | Value |
|--|--|
| Size | Standard |
| Nominal size | 4.3 mm |
| Design | Straight design |
| Container size | 10 |
| Design structure | Push/pull principle |
| Temperature dependent operating pressure | -0.95 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Food-safe | See Supplementary material information |
| Ambient temperature | -20 ... 60 °C |
| Product weight | 7 g |
| Pneumatic connection, port 1 | For tubing outside diameter 8 mm |
| Pneumatic connection, port 2 | For tubing outside diameter 6 mm |
| Materials note | Conforms to RoHS |
| Material housing | PP |
| Material of tube retaining claw | High alloy steel, non-corrosive |