 



# flow control/silencer VFFK-C-K-R18-P

Part number: 133142

FESTO

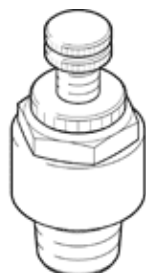

## Data sheet

Feature	Value
Valve function	Flow control – silencer function
Pneumatic connection, port 1	R1/8
Adjusting element	Knurled screw
Mounting type	Threaded
Standard flow rate 0.6-10 MPa (6-10 bar, 87-10 psi)	0 ... 270 l/min
Operating pressure	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Type of seal on screw-in stud	coating
Assembly position	Any
Operating pressure complete temperature range	0 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	0 ... 60 °C
Product weight	13.5 g
Material of silencer insert	PE
Material of threaded plug	Nickel-plated brass
Materials note	Conforms to RoHS
Material adjusting screw	Nickel-plated brass