


braking resistor CACR-KL2-33-W2400

Part number: 1336619

FESTO

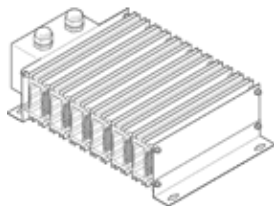

Data sheet

Feature	Value
Size	600
Assembly position	Free convection Vertical
Pulse energy, braking resistor at 380 V	21,600 Ws
Pulse energy, braking resistor at 780 V	21,600 Ws
Performance at 35% duty cycle and 20°C	3,600 W
Rated capacity, braking resistance	1,440 W
Rated output, braking resistor at 380 V	1,440 W
Rated output, braking resistor at 780 V	1,440 W
Resistance value	33 Ohm
Authorisation	c CSA us (OL) c UL us - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Ambient temperature	0 ... 50 °C
Product weight	8,000 g
Mounting type	with through hole with accessories Optional
Materials note	Conforms to RoHS