


clamping sleeve EAMH-145-24-C34-P

Part number: 1354109

FESTO

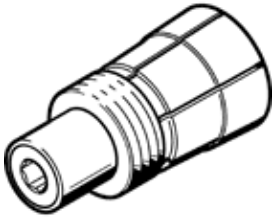

Data sheet

| Feature | Value |
|------------------------|----------------------|
| Size | 145 |
| Assembly position | Any |
| Max. speed | 4,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 34 kgmm ² |
| Product weight | 229 g |
| Materials note | Conforms to RoHS |