

# manifold rail


## VABM-C8-12E-G14-20-M1-L

Part number: 1361875

Classic - do not use for new projects

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

FESTO

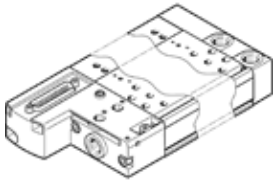

### Data sheet

Feature	Value
Grid dimension	12 mm
Max. number of valve positions	20
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.6 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,296 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy