


# end plate kit NEV-3DA/DB-NPT

Part number: 13997

FESTO

For manifold assembly of standard manifold sub-bases.

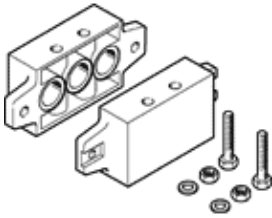

## Data sheet

Feature	Value
Width	190 mm
Operating pressure	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Mounting method for valve	Threaded
Pneumatic connection, port 1	NPT1-11 1/2
Pneumatic connection, port 3	NPT1-11 1/2
Pneumatic connection, port 5	NPT1-11 1/2