


manifold sub-base NAV-1/4-NPT-1C

Part number: 13998

FESTO

With port pattern as per DIN ISO 5599/1, for manifold assembly, connections underneath.

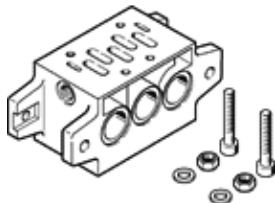

Data sheet

| Feature | Value |
|------------------------------------|---|
| Width | 110 mm |
| Operating pressure | 16 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Mounting method for sub-base | with through hole |
| Pilot air port 12 | NPT1/8-27 |
| Pilot air port 14 | NPT1/8-27 |
| Pneumatic connection, port 2 | NPT1/4-18 |
| Pneumatic connection, port 4 | NPT1/4-18 |