


manifold sub-base NAV-1/2-NPT-3C

Part number: 13999

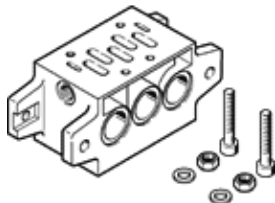

With port pattern as per DIN ISO 5599/1, for manifold assembly,
connections underneath.



Data sheet

Feature	Value
Width	190 mm
Operating pressure	16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pilot air port 12	NPT1/8-27
Pilot air port 14	NPT1/8-27
Pneumatic connection, port 2	NPT1/2-14
Pneumatic connection, port 4	NPT1/2-14