


# axial kit EAMM-A-L48-60H

Part number: 1456611

FESTO

Suitable for electric drives.

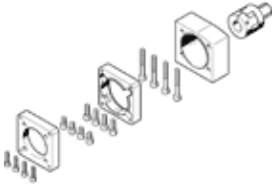

## Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Assembly position        | Any              |
| PWIS conformity          | VDMA24364-B2-L   |
| Storage temperature      | -25 ... 60 °C    |
| Relative air humidity    | 0 - 95 %         |
| Protection class         | IP40             |
| Ambient temperature      | -10 ... 60 °C    |
| Transferable torque      | 12.5 Nm          |
| Product weight           | 430 g            |
| Interface code, actuator | L48              |
| Interface code, motor in | 60H              |
| Materials note           | Conforms to RoHS |