


# barbed T-connector FCN-3-PK-6

Part number: 14770

FESTO

For plastic tubing PAN, PUN, PL, PP, PU.

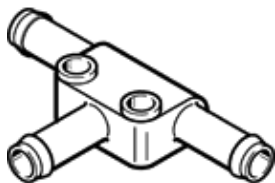

## Data sheet

| Feature                                       | Value   |
|---|---|
| Nominal size                                  | 4.9 mm  |
| Operating pressure complete temperature range | -0.95 ... 10 bar  |
| Operating medium                              | Compressed air in accordance with ISO8573-1:2010 [7:-:-]                    |
| Note on operating and pilot medium            | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity                               | VDMA24364-B1/B2-L   |
| Ambient temperature                           | 0 ... 60 °C   |
| Pneumatic connection, port 1                  | For tubing outside diameter 8 mm  |
| Materials note                                | Conforms to RoHS  |
| Material housing                              | Zinc die-casting  |