


Short AV-12-4-C-S6

Part number: 14772

FESTO

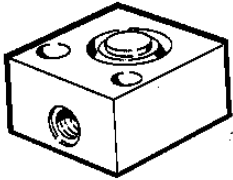

Datasheet

Feature	Value
Mode of operation	Single, pushing
Shape piston	Round
Shape of piston rod	Round
Sensing type	None
Type of cushioning	None
Protection against torsion	None
Piston, nominal size	12
Stroke	4 mm
Piston rod diameter	5 mm
End of piston rod	III
Operating pressure min.	1 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-20 °C
Maximum ambient temperature	150 °C
Air connection type cover cap	Female thread
EE Connecting thread for end cap	M 5
Effective force (theor.) at 6 bar, adv	.58 N
Spring return force min.	3 N
Air consumpt.at 6 bar per advance stro	ke0,0014 l
Medium	Compressed air, filtered