


**coupling**  
**EAMC-67-62-24-32**  
Part number: 1485796

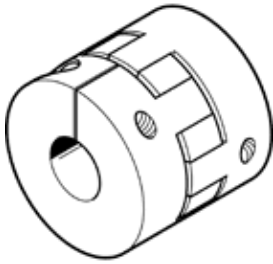

**Data sheet**

<b>Feature</b>	<b>Value</b>
Holder diameter 1	24 mm
Holder diameter 2	32 mm
Size	67
Nominal length	62 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	280 kgmm <sup>2</sup>
Transferable torque	143 Nm
Product weight	428 g
Materials note	Conforms to RoHS