 



# clamping module EV-20-4

Part number: 150683

FESTO

With reset function

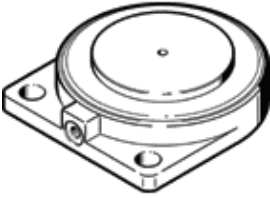

## Data sheet

| Feature                | Value  |
|------------------------|--|
| Stroke                 | 4 mm   |
| Clamping surface       | Ø 20   |
| Assembly position      | Any  |
| Mode of operation      | single-acting  |
| Operating pressure MPa | ≤ 0.6 MPa  |
| Operating pressure     | ≤ 6 bar<br>≤ 87 psi                                      |
| Operating medium       | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| PWIS conformity        | VDMA24364-B1/B2-L  |
| Ambient temperature    | -10 ... 40 °C  |
| Product weight         | 19 g   |
| Mounting type          | with through hole  |
| Pneumatic connection   | M3   |
| Material housing       | Aluminium die cast                                       |
| Material membrane      | TPE-U(PU)  |