


Swivel flange SNGL-80

Part number: 151531
Product to be discontinued

FESTO

For cylinders DNG, DNGU; matching clevis foot mountings LSNG, LSNSG.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

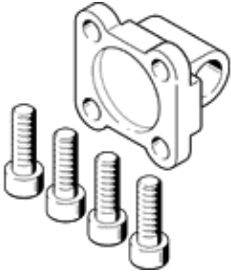

Data sheet

| Feature | Value |
|---|---|
| Size | 80 |
| Conforms to standard | ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance classification CRC | 2 |
| Ambient temperature | -40 ... 90 °C |
| Product weight | 503 g |
| Materials note | Free of copper and PTFE |
| Material information, mounting | Aluminium die cast |
| Materials information for bearing | Plastic |
| Screw material data | Steel Galvanised |