


# One-way flow control valve GRLA-1/8-NPT-RS-B

Part number: 151542

**FESTO**

For exhaust air flow control, with swivel joint.

This product is only available if ordered from the Festo Corporation, USA.

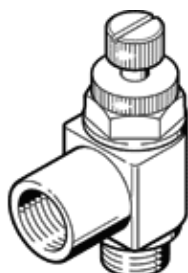

## Data sheet

Feature	Value
Valve function	One-way flow control function for exhaust air
Pneumatic connection, port 1	NPT1/8-27
Pneumatic connection, port 2	NPT1/8-27
Adjusting element	Knurled screw
Mounting type	Threaded
Operating pressure	0.3 ... 10 bar
Ambient temperature	-10 ... 60 °C
Operating medium	Filtered, unlubricated compressed air, 40 µm filtration Filtered, lubricated compressed air, 40 µm filtration
Medium temperature	-10 ... 60 °C