


one-way flow control valve GRLA-3/8-NPT-B

Part number: 151555

FESTO

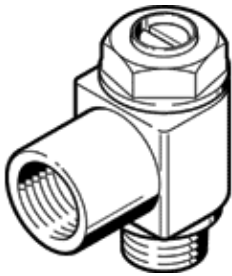

Data sheet

Feature	Value
Valve function	One-way flow control function for exhaust air
Pneumatic connection, port 1	3/8 NPT
Pneumatic connection, port 2	3/8 NPT
Adjusting element	Slotted head screw
Mounting type	Threaded
Ambient temperature	-10 ... 60 °C
Operating pressure complete temperature range	0.3 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Materials note	Conforms to RoHS
Material seals	NBR
Material hollow bolt	Wrought Aluminium alloy
Material adjusting screw	Brass
Material nut	Wrought Aluminium alloy
Material swivel fitting	Zinc die-casting