


# one-way flow control valve GRLA-1/2-NPT-B

Part number: 151559

FESTO

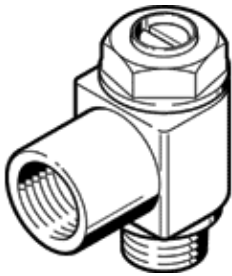

## Data sheet

| Feature                            | Value   |
|------------------------------------|---|
| Valve function                     | One-way flow control function for exhaust air                               |
| Pneumatic connection, port 1       | 1/2 NPT   |
| Pneumatic connection, port 2       | 1/2 NPT   |
| Adjusting element                  | Slotted head screw  |
| Mounting type                      | Threaded  |
| Operating pressure                 | 0.3 ... 10 bar  |
| Ambient temperature                | -10 ... 60 °C   |
| Operating medium                   | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity                    | VDMA24364-B2-L  |
| Medium temperature                 | -10 ... 60 °C   |
| Materials note                     | Conforms to RoHS  |
| Material hollow bolt               | Wrought Aluminium alloy   |
| Material nut                       | Wrought Aluminium alloy   |