


one-way flow control valve GRLA-10-UNF-B

Part number: 151572

FESTO

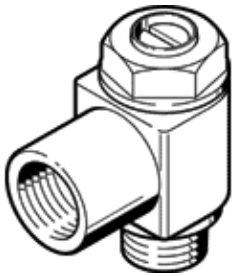

Data sheet

Feature	Value
Valve function	One-way flow control function for exhaust air
Pneumatic connection, port 1	10-32 UNF-2B
Pneumatic connection, port 2	10-32 UNF-2A
Adjusting element	Slotted head screw
Mounting type	Threaded
Operating pressure	0.2 ... 10 bar
Ambient temperature	-10 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Nominal size	2 mm
Materials note	Conforms to RoHS