


# Standard cylinder DNG-4"-8"-PPV-A

Part number: 151636

**FESTO**

Based on ISO 15552, NF E 49 003.1 and UNI 10 290, For proximity sensing, with adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

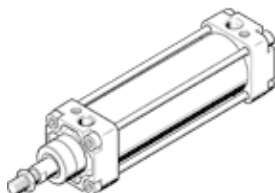

## Data sheet

Feature	Value
Stroke	203.2 mm
Piston diameter	100 mm
Piston rod thread	UNF3/4-16
Cushioning	Pneumatic cushioning, adjustable at both ends (PPV)
Conforms to standard	ISO 6431 VDMA 24562
Piston-rod end	Male thread
Operating pressure	0.6 ... 10 bar
Mode of operation	double-acting
Ambient temperature	-20 ... 80 °C
Cushioning length	36 mm
Theoretical force at 6 bar, return stroke	4,418 N
Theoretical force at 6 bar, advance stroke	4,712 N
Pneumatic connection	M10