


plug socket with cable KMEB-1-230AC-5

Part number: 151691

FESTO

Pre-assembled, for MEBH, MOEBH valves and N2 solenoids.

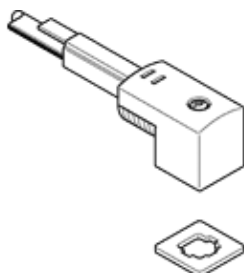

Data sheet

Feature	Value
Assembly position	Any
Product weight	230 g
Electrical connection 1	Socket, to EN 175301-803, type C
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug socket
Electrical connection 1, cable outlet	Angled
Electrical connection 1, note about the cable outlet	90°
Electrical connection 1, number of pins/wires	3
Electrical connection 1, type of mounting	On solenoid valve with M2.5 central screw
Electrical connection 2, connection technology	Open end
Electrical connection 2, number of pins/wires	3
Nominal operating voltage, AC	230 V
Surge strength	4 kV
Protective earth connection	Available
Cable length	5 m
Cable attribute	Standard
Cable diameter	5.2 mm
Cable structure	3x0,5
Wire ends	Wire end ferrule
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA66-GF30
Material seals	NBR
Material electrical contact	Silver-plated copper alloy