


illuminating seal MEB-LD-230AC

Part number: 151718

FESTO

For MEB-valves.

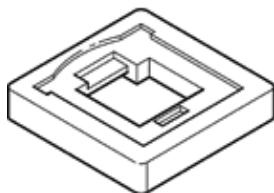

Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M2.5 central screw
Product weight	0.6 g
Electrical connection	Plug pattern type C to EN 175301-803 Per DIN EN 175301-803 Rectangular design, MSEB
Nominal operating voltage, AC	230 V
Surge strength	2.5 kV
Protective earth connection	Available
Nominal power, illuminating seal	0.33 W
Permissible voltage fluctuation	+/- 10 %
Protection class	IP65
Ambient temperature	-25 ... 85 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Degree of contamination	3
Material housing	TPE-U(PU)
Colour	transparent