


# guide unit FENG-1 5/8"- -KF

Part number: 151747

FESTO

with recirculating ball bearing guide, serves for protection against rotation, provides a high accuracy of guidance.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

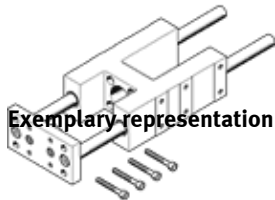

## Data sheet

Feature	Value
Size	1 5/8"
Stroke	0.4 ... 20 "
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide
Ambient temperature	-4 ... 176 °F
Displacement force	15 N
Additional weight per 10 mm stroke	32 g
Basic weight for 0 mm stroke	2,370 g
Mounting type	with internal (female) thread
Material of guide component	Heat-treatment steel
Material housing	Wrought Aluminium alloy