


## quick coupling plug KSS6-3/8-A

Part number: 151780  
Product to be discontinued

FESTO

[For self-closing quick coupling connectors.](#)

[Type to be discontinued. Available until 2018. See Support Portal for alternative products.](#)

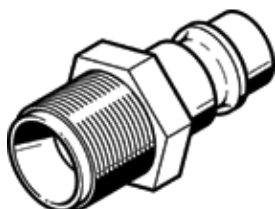

### Data sheet

Feature	Value
Nominal size	7.85 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	1,755 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Authorisation	BIA TÜV
Nominal tightening torque	21.5 Nm
Tolerance for nominal tightening torque	± 15 %
Product weight	27 g
Pneumatic connection, port 1	Male thread G3/8
Materials note	Conforms to RoHS