


# linear drive

## DGO-1"- -PPV-A-B


Part number: 15230



For proximity sensing, rodless, with magnetic coupling.

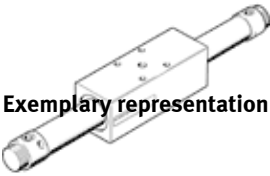

Exemplary representation

 

## Data sheet

| Feature                            | Value   |
|------------------------------------|---|
| Stroke                             | 0.04 ... 157 "  |
| Piston diameter                    | 1"  |
| Cushioning                         | PPV: Pneumatic cushioning adjustable at both ends                           |
| Guide                              | Plain-bearing guide   |
| Driver principle                   | force-locking (magnet)  |
| Operating pressure                 | 1.5 ... 7 bar   |
| Mode of operation                  | double-acting   |
| Operating medium                   | Compressed air in accordance with ISO8573-1:2010 [7:-:-]                    |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity                    | VDMA24364-B2-L  |
| Ambient temperature                | -20 ... 60 °C   |
| Cushioning length                  | 19 mm   |
| Pneumatic connection               | 1/8 NPT   |