



linear drive
DGO-1 1 1/4"- -PPV-A-B
Part number: 15231



For proximity sensing, rodless, with magnetic coupling.

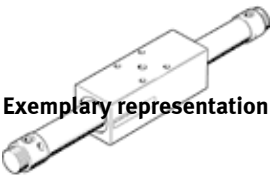

 Exemplary representation



Data sheet

Feature	Value
Stroke	0.04 ... 157 "
Piston diameter	1 1/4"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends
Guide	Plain-bearing guide
Driver principle	force-locking (magnet)
Operating pressure	1.4 ... 7 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 60 °C
Cushioning length	20 mm
Pneumatic connection	1/8 NPT